 


U.I. Lapp GmbH	<h1>DATASHEET</h1>	
	SKINDICHT® SKZ	52005570 14.11.2013

With incised sealing ring for adjustment to several cable diameters
High strain relief
High mechanical stability



Wide clamping range



Optimum strain relief



Robust



Application range

Saddle clamp strain relief gland for harsh application conditions.
Building sites
Plant engineering
Electric motor manufacturing

Design

PG connection thread

Note

SKINDICHT® SKZ-XL is similar to the SKINDICHT® SKZ, but has an extended connection thread for thick walls
Counter nut to be used: SKINDICHT® SM
Refer to SKINDICHT® EV for additional accessories

Remark


Photographs are not to scale and do not represent detailed images of the respective products.

Technical Data

Article designation / size:	SKZ 29
Clamping range ØF (mm):	20 - 29
Max. fitting size for installation (mm):	58
SW1/SW2 mm:	40 / 41
Overall length, C (mm):	46
Thread length, D (mm):	8
Pieces / PU:	10
Caution:	The installation dimensions can be found in appendix T21
Material:	Body: nickel-plated brass Incised sealing ring: CR O-ring: NBR
Protection rating:	IP 55
Temperature range:	-20°C to +80°C

Product Management	Document: SKINDICHT® SKZ	1 / 2
--------------------	--------------------------	-------

U.I. Lapp GmbH	<h1>DATASHEET</h1>	 LAPP GROUP
	SKINDICHT® SKZ	52005570 14.11.2013

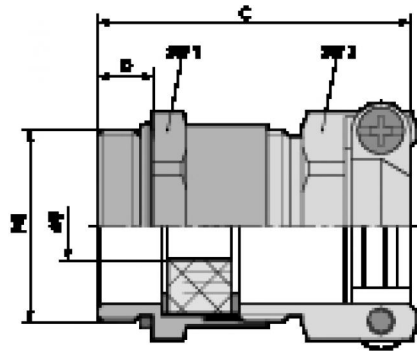

Product Management	Document: SKINDICHT® SKZ	2 / 2
--------------------	--------------------------	-------