 


U.I. Lapp GmbH	<b>DATASHEET</b>	
	<b>SKINTOP® MS-IS-M</b>	<b>53112790</b> <b>29.11.2013</b>

Short connection thread for more space inside the industrial connectors  
Wide, variable clamping ranges  
Optimum strain relief



Industrial machinery and plant engineering



Optimum strain relief



Robust



Connector with standard housing unit



Temperature-resistant

### Application range

Specially designed for use on industrial connectors.

### Design

Metric connection thread acc. to EN 50262

### Note

For suitable multiple seal inserts please see SKINTOP® DIX PG 21 (25 x 1.5) and DIX PG 29 (32 x 1.5)

### Remark


Photographs are not to scale and do not represent detailed images of the respective products.

### Technical Data

Article designation / size:	32 x 1,5
Clamping range ØF (mm):	16-25
SW (mm):	40
Overall length, C (mm):	43
Thread length, D (mm):	5
Caution:	Refer to Appendix T21 for the installation dimensions and torques
Material:	Body: nickel-plated brass Insert: polyamide Sealing ring: CR O-ring: NBR
Protection rating:	IP 68 - 5 bar
Temperature range:	-30°C to +100°C

Product Management	Document: SKINTOP® MS-IS-M	1 / 2
--------------------	----------------------------	-------

U.I. Lapp GmbH	<b>DATASHEET</b>	 <b>LAPP GROUP</b>
	<b>SKINTOP® MS-IS-M</b>	<b>53112790</b> <b>29.11.2013</b>

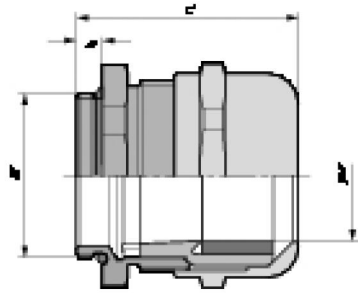

Product Management	Document: SKINTOP® MS-IS-M	2 / 2
--------------------	----------------------------	-------