


Datasheet

Item no. 1302135

V1_0717_01_en

Product Description: Signal lamp, Φ 16mm, 12V.

BN: 1302135

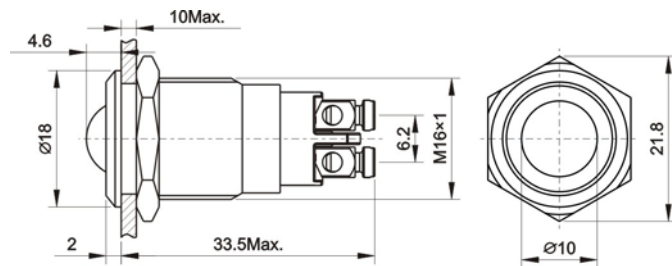

The Front Shape	Domed
Terminal Type	Screw Terminal
Dielectric Intensity	2000VAC
Operating Temp	-20°C ~ +55°C
Humidity	45 ~ 85% RH
Panel Thickness	1~10mm
Rated Voltage	12V AC/ DC
Rated Current	15mA
LED Color	White
LED Life	40000 hours
Torque	5~14Nm
Lampshade Material.....	PC
Body Material	Nickel Plated Brass
Base Material	PBT