


FLRY-A Cable 0.5 mm²

Version 7/15

Item no.: 1370940	Blue	Item no.: 1370946	Yellow
Item no.: 1370941	Black	Item no.: 1370947	Green
Item no.: 1370942	Red	Item no.: 1370948	Grey
Item no.: 1370943	Orange	Item no.: 1370949	Pink
Item no.: 1370944	Brown	Item no.: 1370950	Violet
Item no.: 1370945	White		

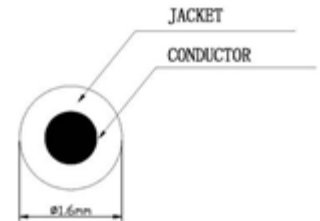

Jacket, outer dimension.....	PVC 1.6mm
No. of conductors.....	19 x 0.19mm
Strand per conductor.....	0.5 mm ²
Length.....	50 meter
Conductor material	copper
Insulation material (with thickness).....	PVC 0.37mm
Core diameter.....	0.85mm
Insulation resistance.....	Min 200M ohm x km
Maximum dielectric strength.....	800V / AC
Temperature range.....	-40 to +105 °C
Rated voltage.....	< DC75 V / AC50 V
Resistance.....	37 mohm/M (20 °C)
Halogen-free.....	N
Lead-free.....	Y
Weight.....	6.5 kg/km