


FLRY-A Cable 2.5 mm²

Version 7/15

Item no.: 1370989	Blue	Item no.: 1370995	Yellow
Item no.: 1370990	Black	Item no.: 1370996	Green
Item no.: 1370991	Red	Item no.: 1370997	Grey
Item no.: 1370992	Orange	Item no.: 1370998	Pink
Item no.: 1370993	Brown	Item no.: 1370999	Violet
Item no.: 1370994	White		

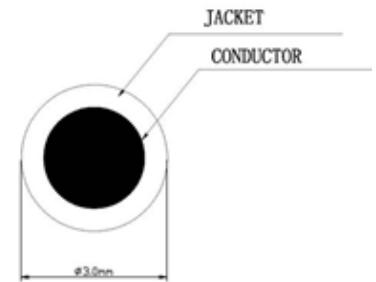

Jacket, outer dimension.....	PVC 3.0mm
No. of conductors.....	19 x 0.41mm
Strand per conductor.....	2.5 mm ²
Length.....	50 meter
Conductor material	copper
Insulation material (with thickness).....	PVC 0.55mm
Core diameter.....	1.9 mm
Insulation resistance.....	Min 200M ohm x km
Maximum dielectric strength.....	1000V / AC
Temperature range.....	-40 to +105 °C
Rated voltage.....	< DC75 V / AC50 V
Resistance.....	7.5 mohm/M (20 °C)
Halogen-free.....	N
Lead-free.....	Y
Weight.....	26 kg/km