


**TECHNICAL SPECIFICATIONS**

**D-Sub Hood:**

Housing material: Zinc, Nickel Plated  
 Operating Temperature: -40°C to +120°C  
 Cable Entry: Top  
 Thumbscrews: UNC 4-40  
 Cable O.D: 13mm Max.

**Male D-Sub Solder Cup:**

Insulator: PBT, Black, UL94 V-0  
 Shell: Steel, Tin Plated  
 Contact pins: Copper Alloy  
 Stamped & Formed Pins: Class 3, 100 inserts min.  
 Contact Plating: Selective Gold over Nickel  
 Operating Temperature: -55°C to +105°C  
 Withstanding voltage: 1000V for 1 minute  
 Insulator resistance: 500MΩ min.

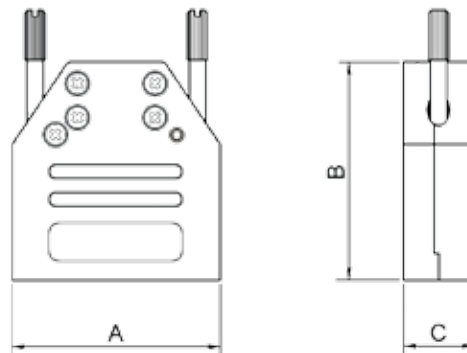

**Features:**

- D-sub hood + D-sub connector solder cup
- Available in sizes 9, 15, 25,37 and 50-way
- Full metall cover
- Packed in Kit with male or female D-sub connector
- Class 3 or Class 1 D-sub connector as standard
- Re-openable

Size MHDTZI	Dim A	Dim B	Dim C
9-way	34,0	45,0	14,6
15-way	43,0	45,0	14,6
25-way	56,5	45,0	14,6
37-way	73,0	45,0	14,6
50-way	71,0	45,0	17,4

**Ordering information:**

**D-Sub Connector Kits (100 inserts min.)**

Size:	P/N - Kitted:	Product Code - MALE Conn. Kit
9-way	6355-0080-01	DTZI09-HDP15-K
15-way	6355-0080-02	DTZI15-HDP26-K
25-way	6355-0080-03	DTZI25-HDP44-K
37-way	6355-0080-04	DTZI37-HDP62-K
50-way	6355-0080-05	DTZI50-HDP78-K

Size:	P/N - Kitted:	Product Code - FEMALE Conn. Kit
9-way	6355-0080-11	DTZI09-HDS15-K
15-way	6355-0080-12	DTZI15-HDS26-K
25-way	6355-0080-13	DTZI25-HDS44-K
37-way	6355-0080-14	DTZI37-HDS62-K
50-way	6355-0080-15	DTZI50-HDS78-K