


# Datasheet

Item no. 1564143

2018-06-01

## Lighter Plug

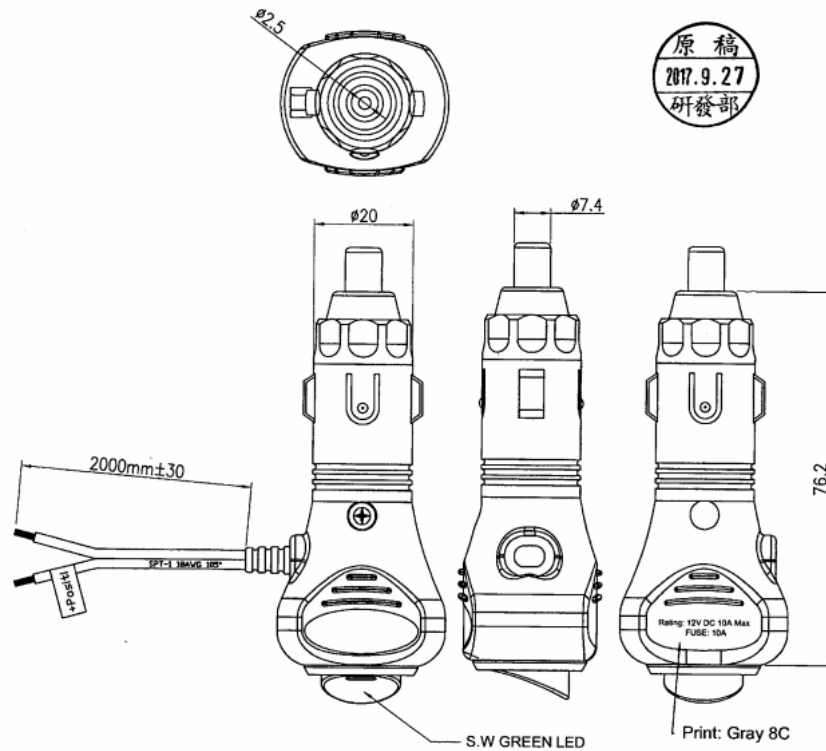

Rating:	12V/ DC 10A
Insulation Resistance:	DC 500V 100M $\Omega$ Min.
Dielectric Strength:	AC 1000V 1 minute
Operation Temperature:	-20°C ~ 60°C
Fuse Type:	250V/ 10A UL AFE (3AG)
Plug Dia.:	20 mm
Wire:	18 AWG
Material:	Housing: Phenolic (UL 94V-1) Top contact: Nickel Plated Metal Spring Contact: Nickel Plated Spring Steel

Lighter plug with ON-OFF illuminated switch