


**Device markers  
THM MT30X 25/12 WS/M**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 16  
D-32758 Detmold  
Germany  
Fon: +49 5231 14-0  
Fax: +49 5231 14-292083  
www.weidmueller.com

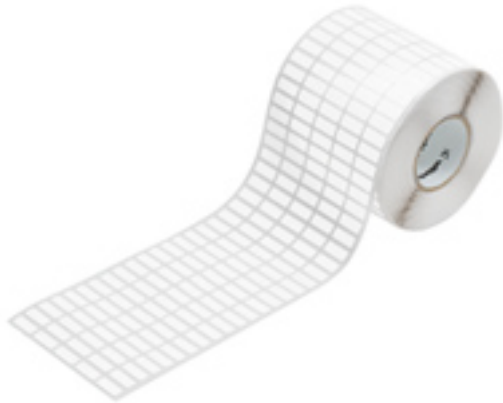

The ThermoMark labels offer brilliant printing quality thanks to the thermal transfer technology. Different materials and the user-friendly printing system under Windows optimise every marking effort.

- High-quality polyester labels in various colours or inexpensive paper labels are available
- Labels are automatically positioned in the printer for perfectly centred prints on each label.

**General ordering data**

Type	THM MT30X 25/12 WS/M
Order No.	<a href="#">1751751044</a>
Version	Device markers, Label, 25 x 12 mm, Polyester, Colour: White
GTIN (EAN)	4032248001361
Qty.	1 pc(s).

## Datenblatt

### Device markers THM MT30X 25/12 WS/M

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com

## Technische Daten

### Dimensions and weights

Length	25 mm	Width	12 mm
Net weight	598.4 g		

### General data

Adhesive	Acrylate adhesive	Colour	White
Material	Polyester	Material colour according to resistance code	9
Number per roll	10,000	Number per sheet	10,000
Operating temperature range, max.	150 °C	Operating temperature range, min.	-29 °C
Printing method	Thermotransfer	UL 94 flammability rating	HB
UL 969 flammability rating	Yes		

### Classifications

ETIM 3.0	EC001288	UNSPSC	30-21-18-01
eClass 5.1	27-14-91-29	eClass 6.2	27-14-91-29
eClass 7.1	27-14-91-29		

### Approvals

Approvals	
ROHS	Conform

### Downloads

M-Print® PRO configuration file [lab\\_thm\\_mt\\_30\\_25\\_12\\_mcf.zip](#)