


**Device markers
THM MT30X 25,9/7,1 WS**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

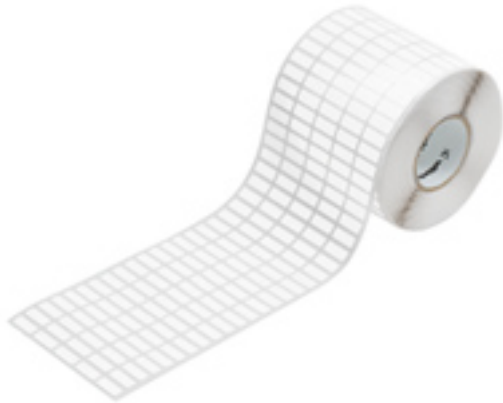

The ThermoMark labels offer brilliant printing quality thanks to the thermal transfer technology. Different materials and the user-friendly printing system under Windows optimise every marking effort.

- High-quality polyester labels in various colours or inexpensive paper labels are available
- Labels are automatically positioned in the printer for perfectly centred prints on each label.

General ordering data

Type	THM MT30X 25,9/7,1 WS
Order No.	1891770000
Version	Device markers, Label, 25.9 x 7.1 mm, Polyester, Colour: White
GTIN (EAN)	4032248504510
Qty.	1 pc(s).

Datenblatt

Device markers THM MT30X 25,9/7,1 WS

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Technische Daten

Dimensions and weights

Length	25.9 mm	Width	7.1 mm
Net weight	205 g		

General data

Adhesive	Acrylate adhesive	Colour	White
Material	Polyester	Material colour according to resistance code	9
Number per roll	5,000	Number per sheet	5,000
Operating temperature range, max.	150 °C	Operating temperature range, min.	-29 °C
Printing method	Thermotransfer	UL 94 flammability rating	HB
UL 969 flammability rating	Yes		

Classifications

ETIM 3.0	EC001288	UNSPSC	30-21-18-01
eClass 5.1	27-14-91-29	eClass 6.2	27-14-91-29
eClass 7.1	27-14-91-29		

Approvals

Approvals	
ROHS	Conform

Downloads

M-Print® PRO configuration file [lab_thm_mt_30_25-9_7-1_mcf.zip](#)