


**W-Series, Accessories
IH 4.8 DB**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

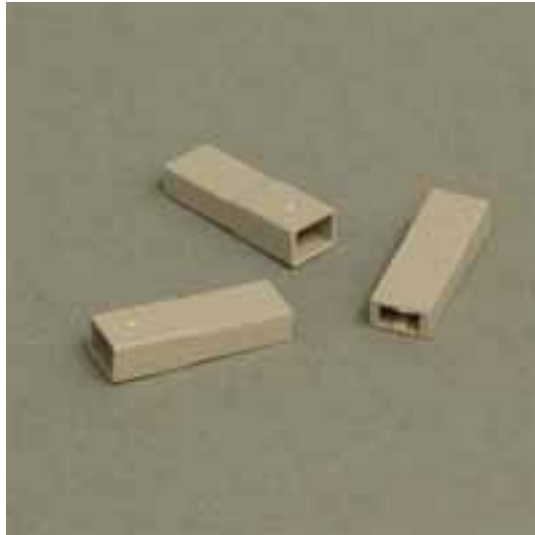

The versatile and extensive range of products - from 0.05 mm² to 300 mm² - means that you have diverse options for your applications at your disposal.
Hardened steel for mechanical strength and high-quality tinned copper for optimum conductivity. All materials comply with RoHS requirements and have been tested to current environment guidelines.

General ordering data

Type	IH 4.8 DB
Order No.	0386160000
Version	W-Series, Accessories, Insulating sleeve
GTIN (EAN)	4008190141004
Qty.	100 pc(s).

W-Series, Accessories IH 4.8 DB

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Technische Daten

Dimensions and weights

Length	22 mm	Width	7 mm
Height	5 mm	Net weight	0.34 g

Temperatures

Operating temperature		Storage temperature	
Continuous operating temp., min.	-50 °C	Continuous operating temp., max.	100 °C

Additional technical data

Explosion-tested version	No	Installation advice	Direct mounting
--------------------------	----	---------------------	-----------------

UL ratings data

Certificate No. (UR)	E60693
----------------------	--------

Material data

Material	PA 66	Colour	Dark Beige, Yellow
UL 94 flammability rating	V-2		

System specifications

Product family	W-Series, Accessories
----------------	-----------------------

Classifications

ETIM 3.0	EC000897	UNSPSC	30-21-18-11
eClass 5.1	27-14-11-45	eClass 6.2	27-14-92-14
eClass 7.1	27-14-92-14		

Approvals

Approvals



ROHS	Conform
------	---------