

Powered PA Speakers

**PA 10/2A**  
**PA 12/2A**  
**PA 15/2A**

**Speaker Connection**

Neuenhofer Strasse 42-44 • D-42657 Solingen • Germany  
 Phone: + 49-(0)212-2 48 58 93 • Fax: + 49-(0)212-2 48 58 90  
 E-Mail: sales@mivoc.com • www.speaker-connection.com

**Features**

- 2-way self powered full range speaker
- Extremely reliable build In class A/B amplifier
- 1/2 Butterfly handles, 2 pcs.
- Customizable aluminium diamond cut logo
- Metal mesh grill woofer protection
- Solid V-groove construction
- Very good price/performance ratio



**PA 10/2A**

**PA 12/2A**

**PA 15/2A**

<b>Type</b>	active 2-way full range speaker	active 2-way full range speaker	active 2-way full range speaker
<b>Driver</b>	10" + 1" horn	12" + 1" horn	15" + 1" horn
<b>Output Power</b>	100 Watts RMS	150 Watts RMS	250 Watts RMS
<b>Impedance (nominal)</b>	8 ohms	8 ohms	8 ohms
<b>SPL 1W/1m / Max.</b>	95 dB	96 dB	98 dB
<b>Frequency range</b>	55 - 20.000 Hz	40 - 20.000 Hz	30 - 20.000 Hz
<b>Connector</b>	In: XLR and 1/4" (6,3mm) phone jack, Out: XLR, 115V	In: XLR and 1/4" (6,3mm) phone jack, Out: XLR, 115V	In: XLR and 1/4" (6,3mm) phone jack, Out: XLR, 115V
<b>Cabinet material</b>	5/8" (15mm) LDF	5/8" (15mm) LDF	5/8" (15mm) LDF
<b>Cabinet surface</b>	Durable HD carpet coating	Durable HD carpet coating	Durable HD carpet coating
<b>Grill</b>	Steel	Steel	Steel
<b>Dimensions (W x H x D)</b>	12 1/5 x 19 3/4 x 12 1/5 inch 310 x 500 x 310 mm	14 1/5 x 24 2/5 x 14 1/5 inch 360 x 620 x 360 mm	17 1/3 x 31 1/2 x 17 1/3 inch 440 x 800 x 440 mm
<b>Weight</b>	31,9 lb / 14,5 kg	45,1 lb / 20,5 kg	62,7 lb / 28,5 kg


Car Audio

Pro Audio

Home Hifi

LED Light

speaker ))) connection

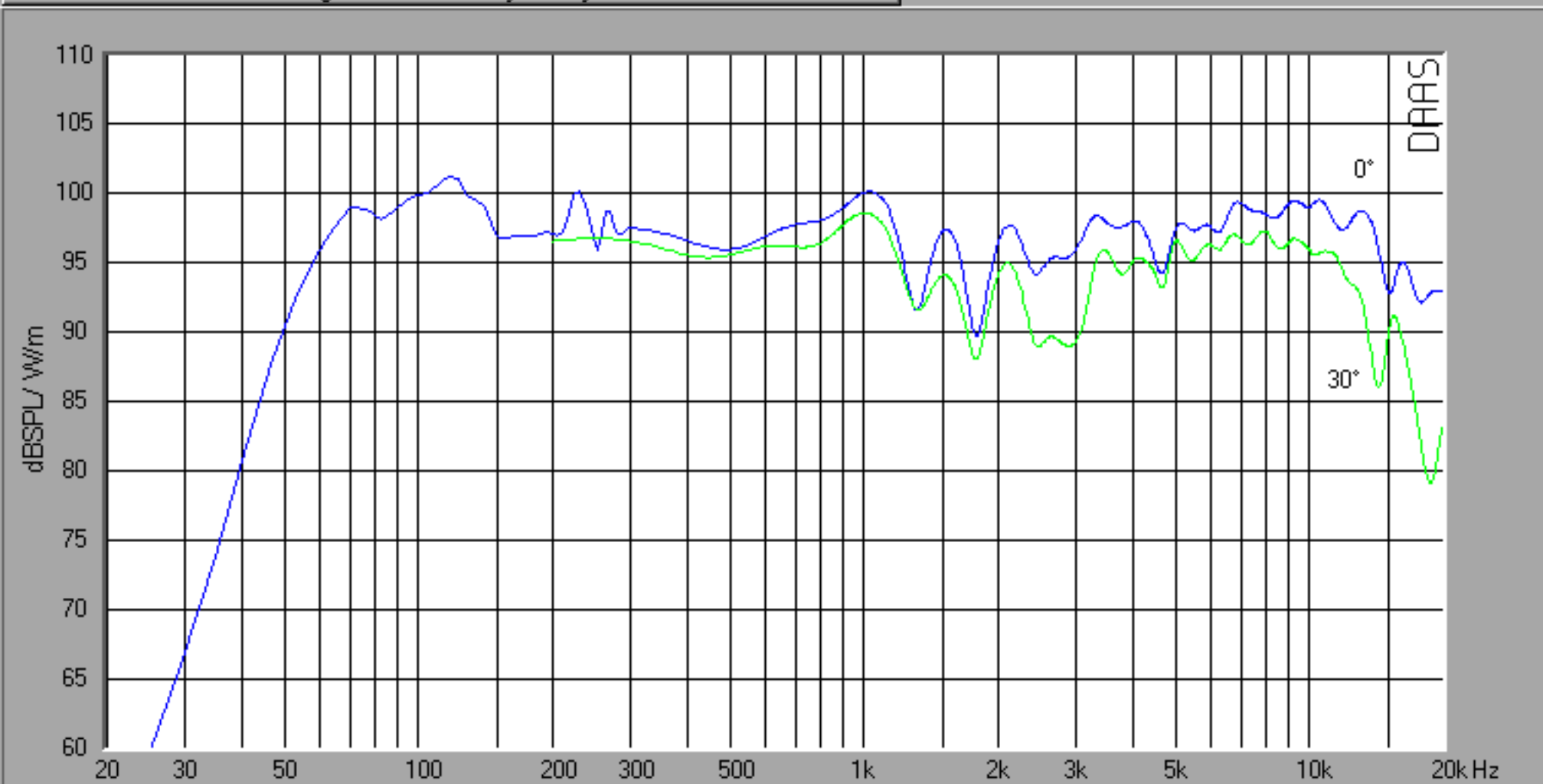

Distance Speaker - Mic.: 100.0cm, dB SPL normalised on 1 Meter, Delay: 2.9ms

Test Signal: PN8192SPL

In1 ± 20V In2 ± 5.9Pa Out 20 dB kHz 48 DUT: McCrypt PA 12/2 (A) SN: 0000 06.04.2009 17:20