


LSM-66A (Artikel-Nr. 335436-07)

EKULIT

SPECIFICATIONS:

TYPE	UNIT	LSM-66A
Impedance	Ω	$8 \pm 15\%$
Power (Nominal)	W	0.2
Power (Maximum)	W	0.3
Resonant Frequency	Hz	$350 \pm 20\%$
Sound Pressure Level	dB	84 ± 3
Frequency Range	Hz	Fo~3.500
Operating Temperature	$^{\circ}\text{C}$	-10~+50
Storage Temperature	$^{\circ}\text{C}$	-20~+60

DIMENSIONS : (Unit: mm)

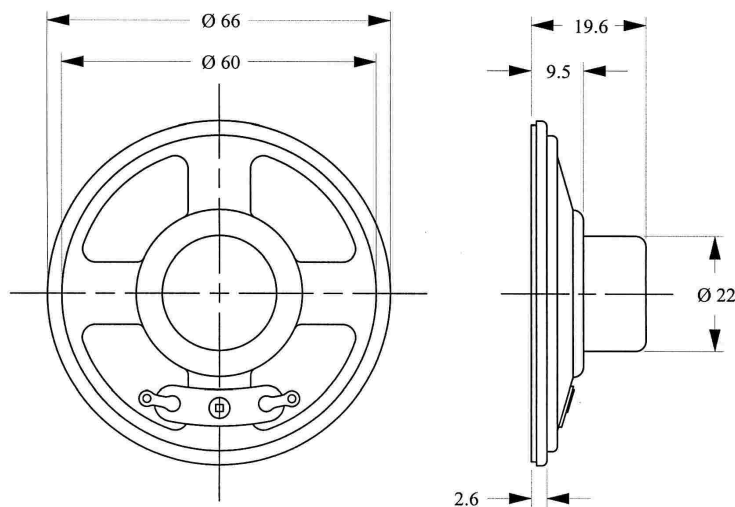

Frequency response:

