

SPE-150/WS


Best.-Nr. 10.1620

SPE-158/WS

Best.-Nr. 10.3150

Einbau-Breitbandlautsprecher

- Hochtonkegel
- Besonders flache Bauform mit festmontiertem Metallgitter
- Geeignet für den Einbau in Decken, Wände und Autotüren

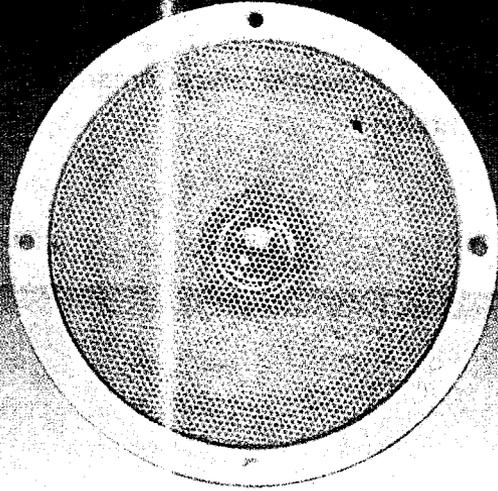

Modell	SPE-85/WS	SPE-130/WS	SPE-165/WS	SPE-150/WS	SPE-158/WS
Impedanz	8Ω	8Ω	8Ω	4Ω	8Ω
Frequenzbereich	350-8000Hz	80-10 000Hz	80-10 000Hz	100-12 000Hz	100-12 000Hz
Belastbarkeit	10W _{MAX} , 5W _{RMS}	40W _{MAX} , 20W _{RMS}	50W _{MAX} , 25W _{RMS}	30W _{MAX} , 15W _{RMS}	30W _{MAX} , 15W _{RMS}
Mittl. Schalldruck (1W/1m)	95dB	85dB	87dB	89dB	88dB
Einbaumaße	-	Ø 110mm x 50mm	Ø 133mm x 60mm	Ø 120mm x 34mm	Ø 120mm x 34mm
Abmessungen	110x110x57mm	Ø 150mm	Ø 180mm	Ø 153mm	Ø 153mm
Gewicht	400g	0,5kg	0,8kg	0,5kg	0,5kg

MONACOR®
International