


## Cable markers CLI M 2-4 GE/SW J MP

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 16  
D-32758 Detmold  
Germany  
Fon: +49 5231 14-0  
Fax: +49 5231 14-292083  
www.weidmueller.com

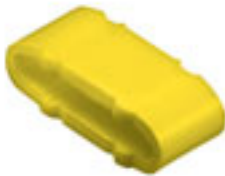

{Reference (Object) not found: prod32188158582590}

### General ordering data

Type	CLI M 2-4 GE/SW J MP
Order No.	<a href="#">1733651655</a>
Version	Cable markers, 4 x 11.3 mm, PVC, soft, without Cadmium, Colour: Yellow
GTIN (EAN)	4008190398149
Qty.	100 pc(s).

## Cable markers CLI M 2-4 GE/SW J MP

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com

## Technische Daten

### Dimensions and weights

Length	4 mm	Width	11.3 mm
Height	3 mm	Depth	3 mm
Net weight	0.13 g		

### General data

Colour	Yellow	Colour of printing	Black
Material	PVC, soft, without Cadmium	Material colour according to resistance code	4
Operating temperature range, max.	80 °C	Operating temperature range, min.	-30 °C
Orientation of print	horizontal	Printed characters	Upper-case letters
Printing	J	Printing method	Laser print
Recommended industries	Process, Machinery	Type of printing	Standard
UL 94 flammability rating	V-0		

### Conductor and cable markers

Conductor O.D., max.	317 mm	Conductor O.D., min.	10 mm
Conductor cross-section, max.	500 mm <sup>2</sup>	Conductor cross-section, min.	16 mm <sup>2</sup>

### Classifications

ETIM 3.0	EC001530	UNSPSC	44-12-17-08
eClass 5.1	27-14-91-03	eClass 6.2	27-14-91-29
eClass 7.1	27-14-91-29		

### Approvals

Approvals	
ROHS	Conform

**Datenblatt**

**Cable markers**  
**CLI M 2-4 GE/SW J MP**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 16  
D-32758 Detmold  
Germany  
Fon: +49 5231 14-0  
Fax: +49 5231 14-292083  
[www.weidmueller.com](http://www.weidmueller.com)

**Zeichnungen**



Product is similar to illustration