
 
 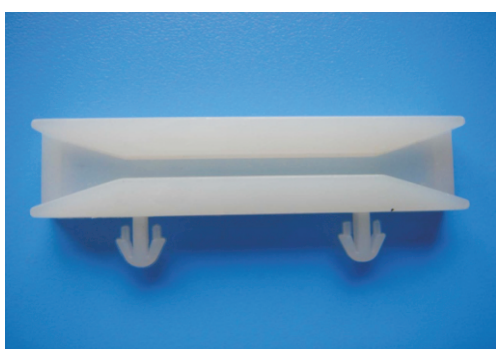


NUIT: mm±0.3





MATERIAL:NYLON 66(UL)
 FLAME CLASS:94V-2
 COLOR:NATURAL


Item No.	A	B	C	D	E	F
HCG38-2	38.8	20.0	9.3	6.0	3.0	3.0
HCG80-2	81.3	60.0	8.2	6.0	3.0	3.0
HCG90-2	91.5	71.0	8.0	6.0	3.0	3.0



  MONTING HOLES





NUIT: mm±0.3

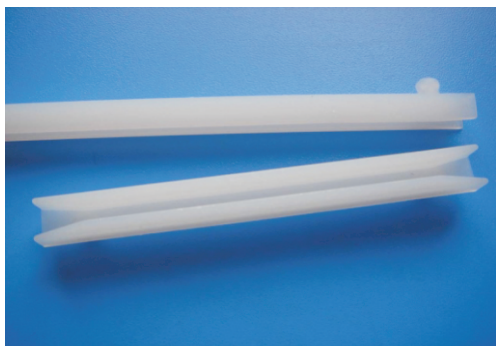

MATERIAL:NYLON 66(UL)
 FLAME CLASS:94V-2
 COLOR:NATURAL

Item No.	A	B
CG-250	64.0	50.8
CG-300	75.5	63.0
CG-350	88.4	75.5
CG-400	101.0	88.5
CG-450	114.0	101.6
CG-500	127.0	114.3
CG-550	139.0	126.5
CG-600	152.4	139.7

 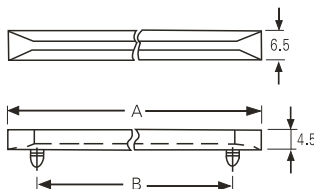

MOUNTING HOLES

CHASSIS THICKNESS: 0.8-1.2

