


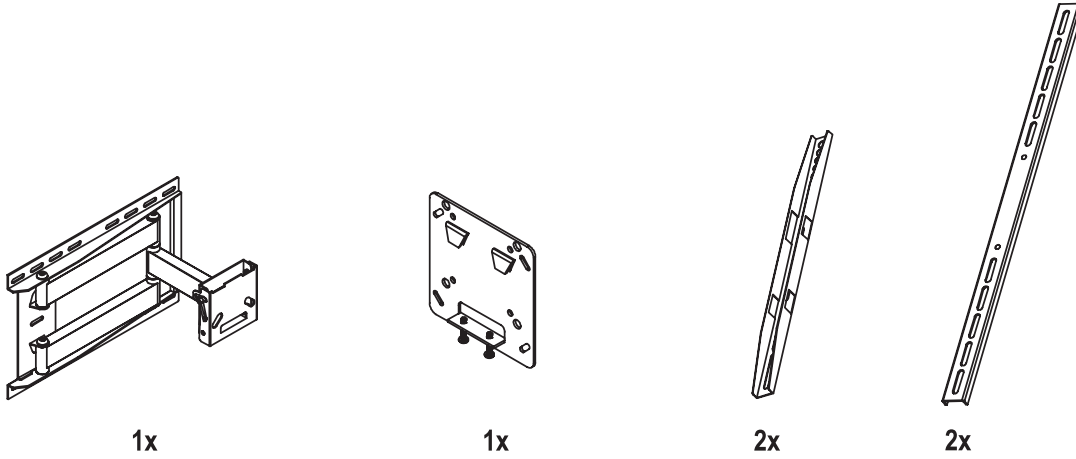










 


Best.-Nr. / ItemNo. / N° de commande / Bestnr. 52 75 04




1

			
A 4x	B 4x	C M6/M8 8x	D M8x14 8x


						
E M5x12 4x	F M6x12 4x	G M8x16 4x	H M5x30 4x	I M6x35 4x	J M8x40 4x	J1 M8x20 4x
						
K M5 4x	L 1x	M 1x				

2

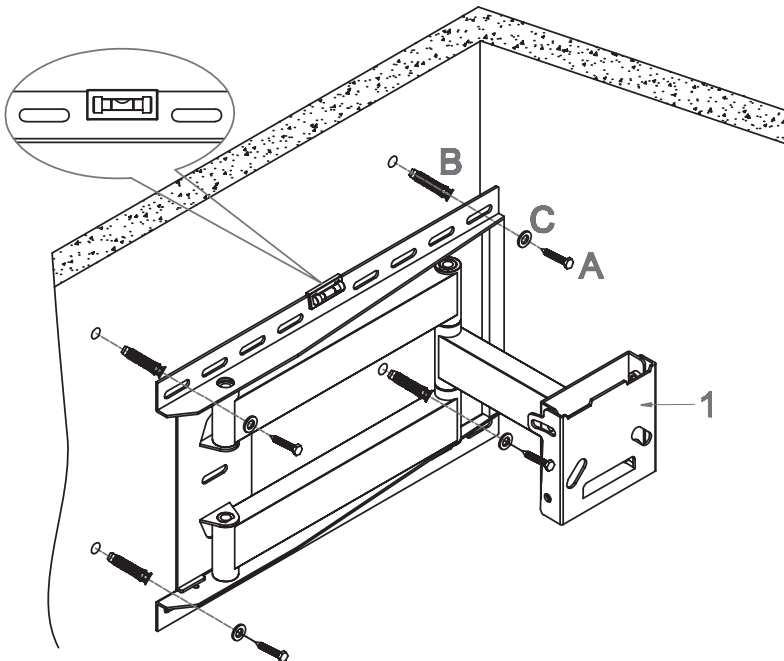


VESA 75x75 / 100x100:

3

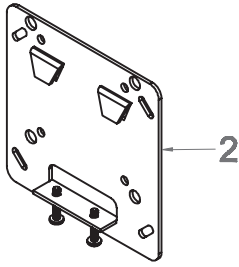


VESA max. 600x400:

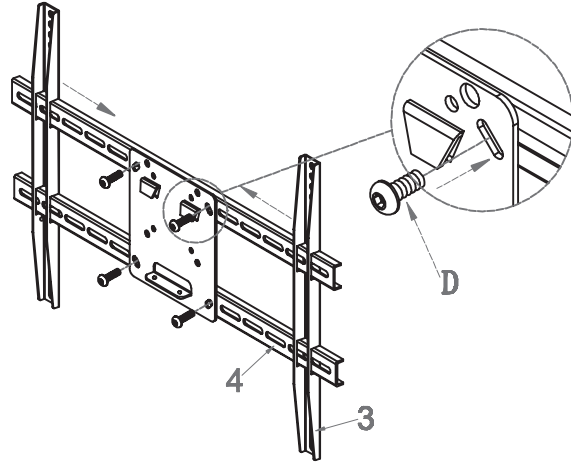


4

VESA 75x75 / 100x100:

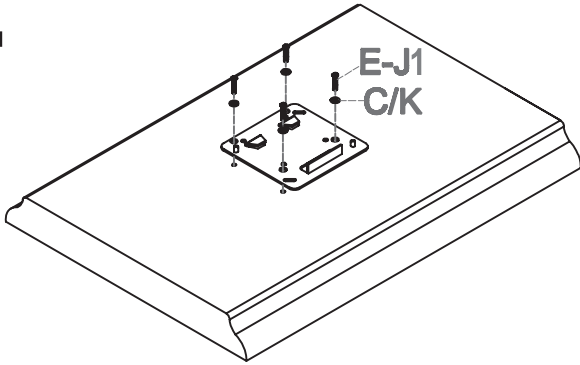

VESA max. 600x400:

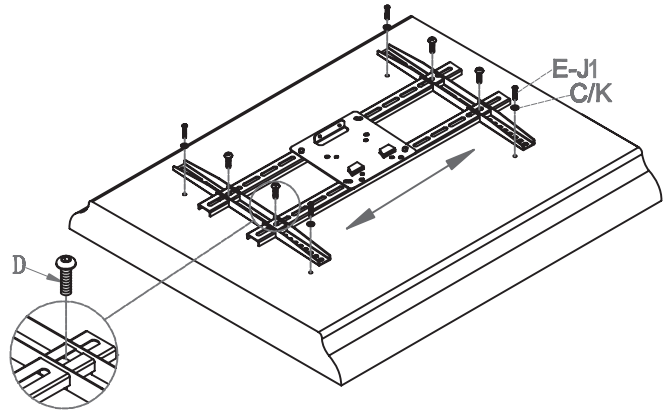

5

