






Locknuts, metric

Gegenmuttern, metrisch

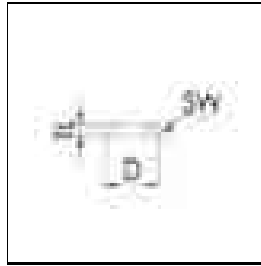

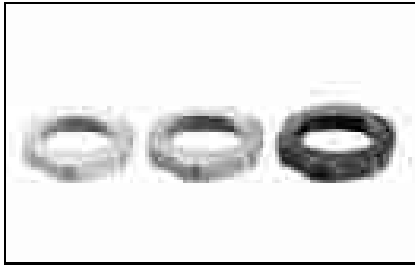

 
Temperature range: -40°C to 100°C, intermittent to approx. 150°C
Material: Polyamide / reinforced glass fibre

Einsatztemperatur: -40°C bis 100°C, kurzzeitig bis ca. 150°C
Material: Polyamid / glasfaserverstärkt

| Type | WISKA-No. RAL 7035 □ 100. | WISKA-No. RAL 9005 ■ 100. | WISKA-No. RAL 7001 ■ 100. |  |  mm |  mm | TL mm |
|---------|---------------------------------|---------------------------------|---------------------------------|---|---|---|----------|
| EMUG 12 | 60770 | 61780 | 62712 | 100/1000 | M 12x1,5 | 18 | 5 |
| EMUG 16 | 60771 | 61781 | 62713 | 100/1000 | M 16x1,5 | 22 | 5 |
| EMUG 20 | 60772 | 61782 | 62714 | 100/1000 | M 20x1,5 | 27 | 5 |
| EMUG 25 | 60773 | 61783 | 62715 | 100 | M 25x1,5 | 32 | 6 |
| EMUG 32 | 60774 | 61784 | 62716 | 100 | M 32x1,5 | 40 | 6 |
| EMUG 40 | 60775 | 61785 | 62717 | 50 | M 40x1,5 | 50 | 7 |
| EMUG 50 | 60776 | 61786 | 62718 | 25 | M 50x1,5 | 60 | 7 |
| EMUG 63 | 60777 | 61787 | 62719 | 10 | M 63x1,5 | 75 | 7 |

Locknuts, PG

Gegenmuttern, PG

| Type | WISKA-No. RAL 7035 □ 100. | WISKA-No. RAL 9005 ■ 100. |  |  mm |  mm | TL mm |
|----------|---------------------------------|---------------------------------|---|---|---|----------|
| MUG 7 | 60670 | 60680 | 100/1000 | PG 7 | 19 | 5 |
| MUG 9 | 60671 | 60681 | 100/1000 | PG 9 | 22 | 5 |
| MUG 11 | 60672 | 60682 | 100/1000 | PG 11 | 24 | 5 |
| MUG 13,5 | 60673 | 60683 | 100/1000 | PG 13,5 | 27 | 6 |
| MUG 16 | 60674 | 60684 | 100/1000 | PG 16 | 30 | 6 |
| MUG 21 | 60675 | 60685 | 100/1000 | PG 21 | 36 | 7 |
| MUG 29 | 60676 | 60686 | 50 | PG 29 | 46 | 7 |
| MUG 36 | 60677 | 60687 | 25 | PG 36 | 60 | 8 |
| MUG 42 | 60678 | 60688 | 25 | PG 42 | 73 | 8 |
| MUG 48 | 60679 | 60689 | 10 | PG 48 | 78 | 8 |