

Data sheet | Item number: 280-801/281-411

Diode module; with diode 1N4007; 5 mm wide


www.wago.com/280-801/281-411



RoHS
Compliant

[BOMcheck.net](https://www.bomcheck.net)

Color:

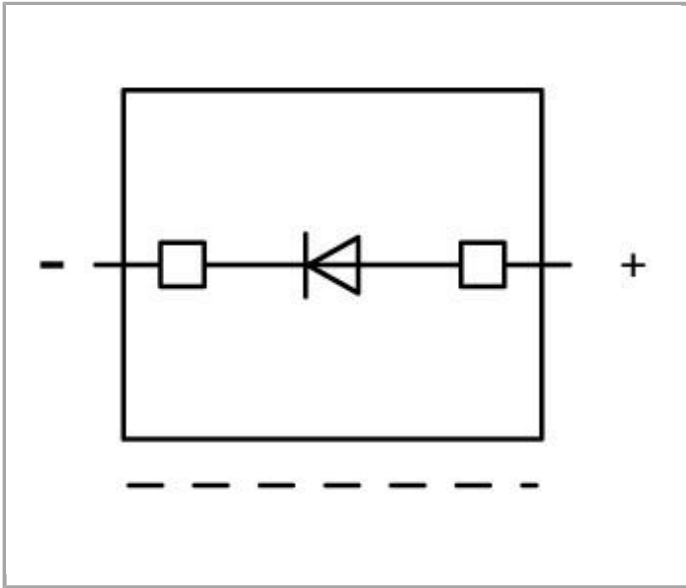

Data

Electrical data

Nominal voltage	250 V
Reverse voltage	1000 V

Ratings per IEC/EN 60664-1

Rated current	0.5 A
---------------	-------

Geometrical Data

Width	5 mm / 0.197 inch
Plug width	5 mm / 0.197 inch

Material Data



 


Color	gray
Insulating material	Polyamide 66 (PA 66)
Fire load	0.066 MJ
Weight	2.6 g

Commercial data

Country of origin	DE
GTIN	4045454195595
Customs Tariff No.	85369010000
Product Group	1 (Rail Mounted Terminal Blocks)

Compatible products

clamps

	Item no.: 280-610 3-conductor carrier terminal block; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm ² ; CAGE CLAMP®	www.wago.com/280-610
	Item no.: 280-616 2-conductor carrier terminal block; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm ² ; CAGE CLAMP®	www.wago.com/280-616
	Item no.: 280-686 4-conductor carrier terminal block; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm ² ; CAGE CLAMP®	www.wago.com/280-686
	Item no.: 280-816 4-conductor carrier terminal block; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm ² ; CAGE CLAMP®	www.wago.com/280-816
	Item no.: 280-916 2-conductor carrier terminal block; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm ² ; CAGE CLAMP®	www.wago.com/280-916

Downloads

Documentation

Bid Text

280-801/281-411	Oct 12, 2017	DOC 23.6 kB	Download
-----------------	--------------	----------------	----------

smartDATA

CAD data

3D Download 280-801/281-411	URL	Download
-----------------------------	-----	----------

Subject to changes.