

HC-B 16-KMQ-H-O1STM32


Order No.: 1460312



<http://catalog.phoenixcontact.net/phoenix/treeViewClick.do?UID=1460312>

HEAVYCON B16 coupling housing, with double locking latch, height:
82 mm, with 1 x M32 thread, straight cable outlet

Commercial data

| | |
|--------------------------|---|
| EAN |  4 046356 695794 |
| sales group | D002 |
| Pack | 10 Pcs. |
| Customs tariff | 85389099 |
| Gross weight in pieces | KG |
| Net weight per piece | KG |
| Catalog page information | Page 516 (CAT-4-2013) |

[http://
www.download.phoenixcontact.com](http://www.download.phoenixcontact.com)
Please note that the data given
here has been taken from the
online catalog. For comprehensive
information and data, please refer
to the user documentation. The
General Terms and Conditions of
Use apply to Internet downloads.

Certificates / Approvals

Certification

Certifications applied for:


Certification Ex:

Accessories

| Item | Designation | Description |
|----------------|--------------------|---|
| General | | |
| 1690642 | HC-K-KV-M32(15-21) | Plastic screw connection up to 5 bar, thread length: 10 mm, cable diameter: 15 - 21 mm, WAF 36, screw connection: M32 |
| 1690587 | HC-M-KV-M32(14-21) | Metal screw connection up to 5 bar, thread length: 8 mm, cable diameter: 14 - 21 mm, WAF 34, screw connection: M32 |
| 1646010 | HC-M-KV-M32(19-27) | Metal screw connection up to 5 bar, thread length: 8 mm, cable diameter: 19 - 27 mm, WAF 43, screw connection: M32 |

Drawings

Dimensioned drawing

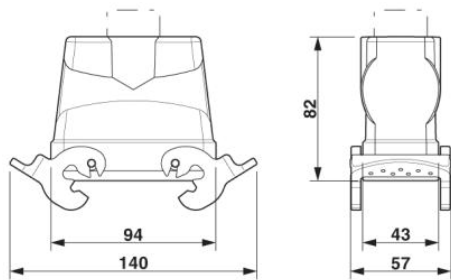

Dimensional drawing

Address

PHOENIX CONTACT GmbH & Co. KG
Flachmarktstr. 8
32825 Blomberg, Germany
Phone +49 5235 3 00
Fax +49 5235 3 41200
<http://www.phoenixcontact.com>



© 2012 Phoenix Contact
Technical modifications reserved;