


BB12B Back horn

bb灯泡 12V 技术参数

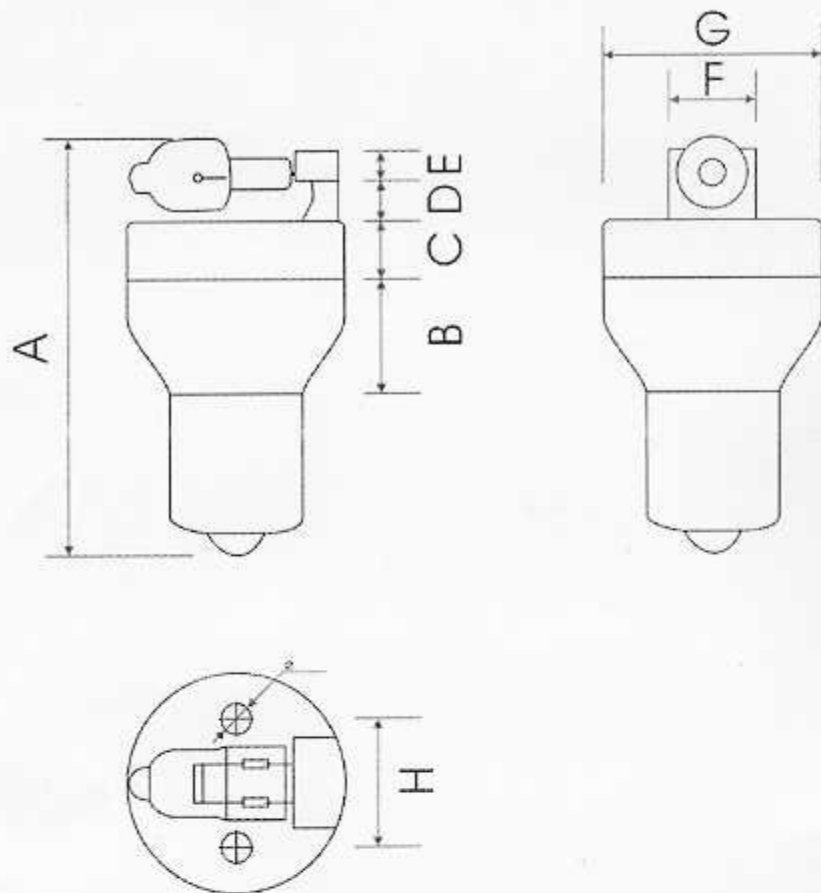

Dimensions in mm

| | | | | |
|-----------------|--------------------|-------------------|----|----|
| A: 49 ± 0.5 | B: 13 ± 0.2 | C: 2.8 ± 0.1 | D: | E: |
| F: 10 ± 0.1 | G: Dia. $27 - 0.2$ | H: 16.8 ± 0.1 | | |

Cap BA15S in accordance with IEC publication 60060 (sheet 7004-11A-9) 2/

ELECTRICAL AND PHOTOMETRIC CHARACTERISTICS

| Rated values | | Objective | | |
|----------------------|----------------|---|---------------|--------------------------------|
| Buzzer 蜂鸣器 | Volts | 12 V | Volts | 13.2 |
| | Watts | 0.4 W | Watts | 23.9 |
| | Work temp. | $-20 \sim +85 \text{ }^{\circ}\text{C}$ | Work temp. | $+25 \text{ }^{\circ}\text{C}$ |
| | Life | 10000 h | Decibel | 82.5 db |
| | Low frequency | 60 Hz | Life | $\geq 200 \text{ h}$ |
| | High frequency | 1.25 Hz | Luminous flux | 250 lm |
| | Decibel | $\geq 60 \text{ db}$ | | |
| Lamp 灯泡 | Volts | 12 | | |
| | Watts | 20 | | |
| | life | 500 | | |
| | Luminous flux | 500 | | |