

2825

ORIGINAL | Lamps with glass wedge bases



Product benefits

- Wide product range
- Reliable quality

Product features

- Original spare parts

Product datasheet

Technical data


Electrical data

Power input	5 W
Nominal voltage	12.0 V
Nominal wattage	5.00 W
Power input tolerance	±10 %
Test voltage	13.5 V

Photometrical data

Luminous flux	50 lm
Luminous flux tolerance	±20 %

Dimensions & weight

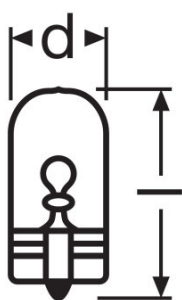

Length	26.8 mm
Diameter	10.0 mm
Product weight	1.30 g

Lifespan

Lifespan B3	350 h
Lifespan Tc	1000 h

Additional product data

Base (standard designation)	W2.1x9.5d
-----------------------------	-----------

Certificates & standards

ECE category	W5W
--------------	-----

Country specific categorizations

Product datasheet

Order reference	2825 5W12VW2,1X
------------------------	-----------------

Country specific information

Product code	METEL code	SEG number	STK number	UK Org
4050300838632	OSRA2825	8328258	4739284	-
4050300925684	OSRA2825BLI2	-	4730323	-

Product datasheet

Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Volume	Gross weight
4008321117274	2825	Unpacked 1	- x - x -		
4008321117281	2825	Folding carton box 450	- x - x -		
4008321117298	2825	Shipping carton box 3600	310 mm x 285 mm x 160 mm	14.14 dm ³	5027.00 g
4008321163578	2825	Unpacked 1	- x - x -		
4008321021885	2825	Folding carton box 10	- x - x -		
4008321021892	2825	Shipping carton box 100	210 mm x 113 mm x 84 mm	1.99 dm ³	600.00 g
4008321174093	2825	Unpacked 1	- x - x -		
4008321174109	2825	Folding carton box 450	140 mm x 71 mm x 136 mm	1.35 dm ³	625.00 g
4008321174116	2825	Shipping carton box 3600	310 mm x 160 mm x 285 mm	14.14 dm ³	5243.00 g
4008321245786	2825	Unpacked 1	140 mm x 40 mm x 136 mm	0.76 dm ³	6.00 g
4008321245793	2825	Shipping carton box 3600	310 mm x 160 mm x 311 mm	15.43 dm ³	148923.00 g
4050300556956	2825	Unpacked 1	22 mm x 8 mm x 14 mm	0.00 dm ³	1.00 g
4050300778839	2825	Shipping carton box 3600	310 mm x 160 mm x 285 mm	14.14 dm ³	5053.33 g
4050300838632	2825	Unpacked 1	30 mm x 11 mm x 14 mm	0.00 dm ³	2.30 g
4050300524801	2825	Folding carton box 10	40 mm x 42 mm x 106 mm	0.18 dm ³	20.80 g
4008321094469	2825	Shipping carton box 50	148 mm x 71 mm x 98 mm	1.03 dm ³	146.36 g
4050300887951	2825	Unpacked 1	22 mm x 8 mm x 9 mm	0.00 dm ³	1.00 g
4050300887968	2825	Folding carton box 450	140 mm x 83 mm x 136 mm	1.58 dm ³	625.00 g
4050300887975	2825	Shipping carton box 3600	310 mm x 160 mm x 285 mm	14.14 dm ³	5243.00 g
4050300888712	2825	Unpacked 1	12 mm x 3 mm x 6 mm	0.00 dm ³	1.00 g
4050300888729	2825	Folding carton box 450	135 mm x 74 mm x 140 mm	1.40 dm ³	610.33 g

Product datasheet

4050300888736	2825	Shipping carton box 3600	310 mm x 160 mm x 285 mm	14.14 dm ³	5119.00 g
4050300925684	2825	Blister 2	75 mm x 9 mm x 46 mm	0.03 dm ³	7.60 g
4008321140340	2825	Shipping carton box 20	123 mm x 105 mm x 92 mm	1.19 dm ³	116.80 g
4052899340367	2825	Unpacked 1	- x - x -		
4052899340374	2825	Folding carton box 10	- x - x -		
4052899340381	2825	Shipping carton box 50	148 mm x 115 mm x 55 mm	0.94 dm ³	150.00 g
4052899340398	2825	Unpacked 1	- x - x -		
4052899340404	2825	Folding carton box 450	- x - x -		
4052899340411	2825	Shipping carton box 3600	310 mm x 285 mm x 160 mm	14.14 dm ³	5243.00 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.