




1. Production outlines (Moulded IEC 169-2(m) to IEC 169-2(f) TV Hook-Up Cable, Connectors: 100% Shielded)

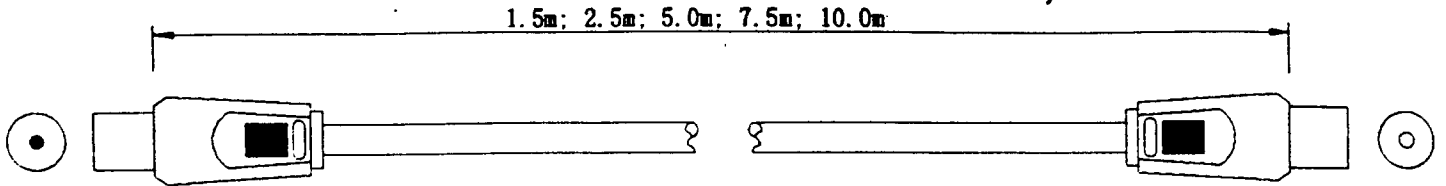

2. Structure of cable

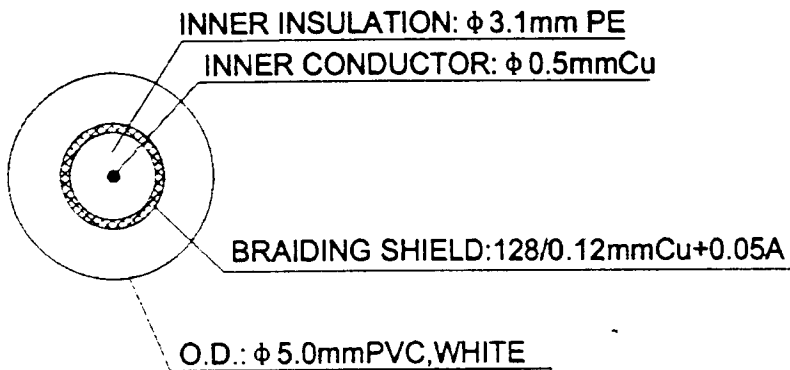

 3. Wiring diagram



SPECIFICATION

Attenuation(dB/100m)

50MHz	\leq 10.1
100MHz	\leq 13.5
200MHz	\leq 18.9
300MHz	\leq 23.0
470MHz	\leq 29.1
860MHz	\leq 40.5
1000MHz	\leq 44.1
1350MHz	--
1750MHz	--
2050MHz	--
2250MHz	--
2400MHz	--

Screening Factor(dB)

50~300MHz	\geq 95
300~470MHz	\geq 90
470~1000MHz	\geq 90
1000~2400MHz	—

Return Loss(dB)

50~470MHz	\geq 20
470~1000MHz	\geq 18
1000~2400MHz	--

Operation temperature: -25°C to +75°C